

7433501020	DATA SHEET	
Valid from: 19.02.2026	EPIC® MC04C1LSAB22RK20	

Description

- Sensor/actuator TPU-cable, unshielded
- M12 Connector, A-coding, 4 Pin



Product variations

Article no.	Article description	P1 - cable end	P2 - cable end	Length (mm)
7433501020	EPIC® MC04C1LSAB22RK20	connector, straight	Open end	2000 +100/-20
7433501021	EPIC® MC04C1LSAB22RK50	connector, straight	Open end	5000 +150/-30
7433501076	EPIC® MC04C2LSAB22RK20	coupling, straight	Open end	2000 +100/-20
7433501077	EPIC® MC04C2LSAB22RK50	coupling, straight	Open end	5000 +150/-30

Other lengths are available on request.

Connector, general characteristics

Coding	A-Coding
Number of poles / pins	4
Product standard	IEC 61076-2-101 (2024)
Shielded	No
Protection class	IP 67
Pollution degree	3
Ambient temperature (connected)	-25 up to +80°C (Flexible) -40 up to +80°C (Fixed)
Plugging cycles	≥ 100
Tightening torque	Recommended:0.4 Nm Max:0.8 Nm

Connector, electrical properties

Rated voltage	250V AC / DC
Rated surge voltage	2500 V
Rated current	4 A
Insulation resistance	≥ 100 MΩ
Contact resistance of connector	≤ 5 mΩ

Connector, materials

Contacts- Male connector	Brass, gold plated
Contacts- Female connector	Phosphor, gold plated
Insert	PA66+GF
Overmold	TPU/ Black
Threaded part	Brass, nickel plated
Sealing	FKM

Creator: Drake Long / PDCF Released: SOLI1 / PDCF	Document: DB7433501020EN Version: 00	Page 1 of 3
--	---	-------------

7433501020	DATA SHEET	
Valid from: 19.02.2026	EPIC® MC04C1LSAB22RK20	

Cable, general characteristics

AWM style	UL20549
Conductor cross-section	22 AWG (0.34mm ²)
Number of conductors	4 (1. Brown, 2. White, 3. Blue, 4. Black)
Core outer diameter	1.2 ±0.1mm
Jacket outer diameter	4.5±0.2mm
Cable weight	26.7 ± 3 kg/km
Temperature rating	-40 up to +80°C
Halogen-free	No
Flammability test	H ; CSAFT2
Oil resistance	No

Cable, electrical properties

Rated voltage	300 V
Conductor resistance-3 Pin	MAX 55.4 Ω/km at 20°C
Conductor resistance-4 Pin	MAX 59.4 Ω/km at 20°C
Dielectric strength	2000V / min.



Cable, materials

Conductor	Tinned copper
Conductor insulation	HD-PE
Jacket	TPU, Black


Creator: Drake Long / PDCF Released: SOLI1 / PDCF	Document: DB7433501020EN Version: 00	Page 2 of 3
--	---	-------------

7433501020	DATA SHEET	
Valid from: 19.02.2026	EPIC® MC04C1LSAB22RK20	


Drawings

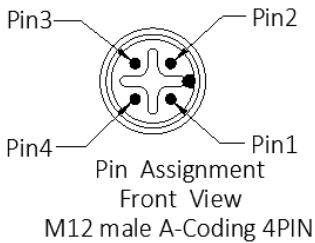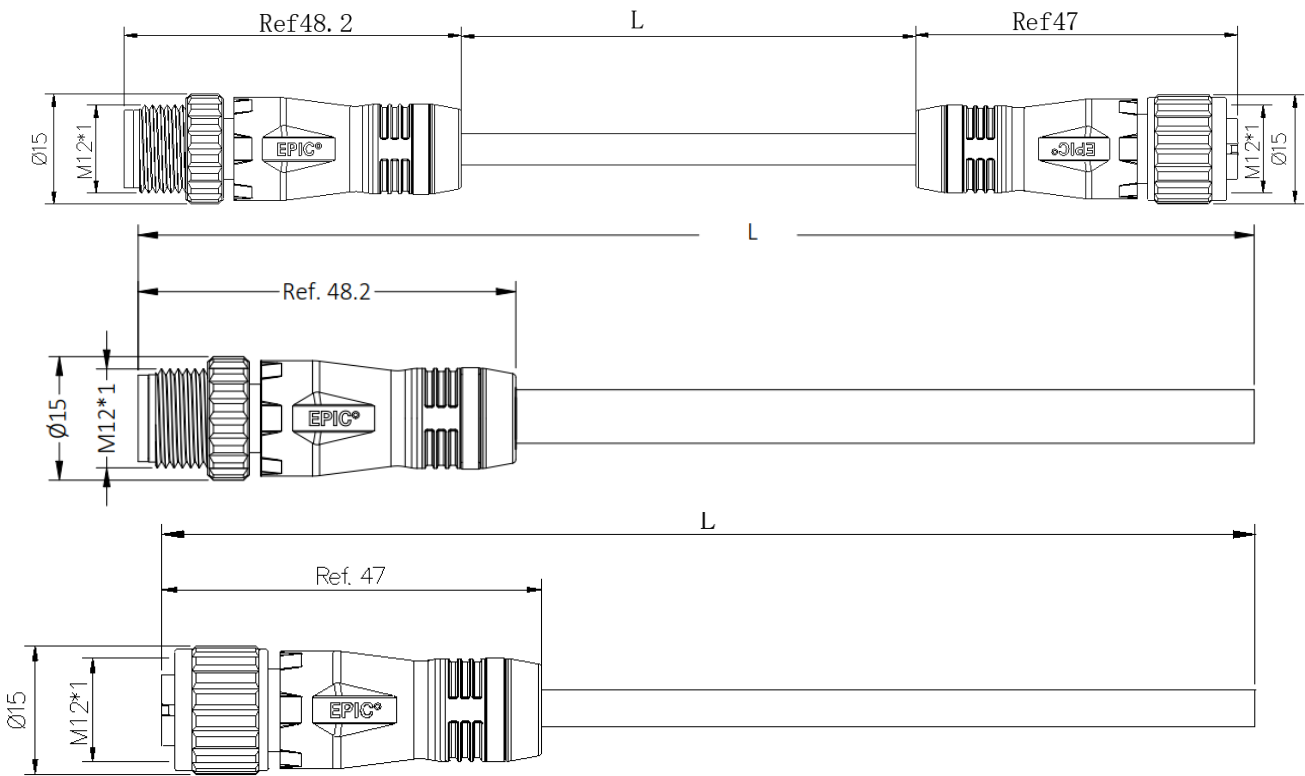

Wire List			
P1(male)		P2(female)	
PIN 1	Brown (AWG 22)	PIN 1	
PIN 2	White (AWG 22)	PIN 2	
PIN 3	Blue (AWG 22)	PIN 3	
PIN 4	Black (AWG 22)	PIN 4	

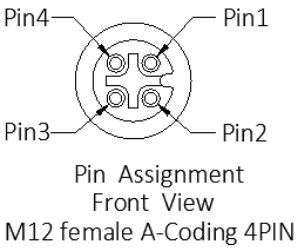

Cross section

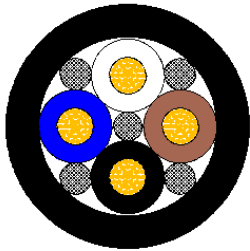

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Creator: Drake Long / PDCF Released: SOLI1 / PDCF	Document: DB7433501020EN Version: 00	Page 3 of 3
--	---	-------------