


61850760	DATA SHEET	
Valid from: 13.04.2026	CABLE TIE TWIST	

The CABLE TIE TWIST all-purpose cable tie, made from polyamide, is suitable for a wide range of applications thanks to its high tensile strength.

Material: Polyamide 6.6

Technical features:

Bundle diameter max. 102 mm
 Band width 4,8 mm
 Tensile strength 222 N

Additional features:

Fire classification V2 acc. to UL 94
 Twist and cut

Temperature range: 0°C up to +85°C

Colour: Black

Approbation:




E-File E352714

Norm Reference:



EN 62275

(Cable ties marked with an * have been tested in accordance with EN 62275)

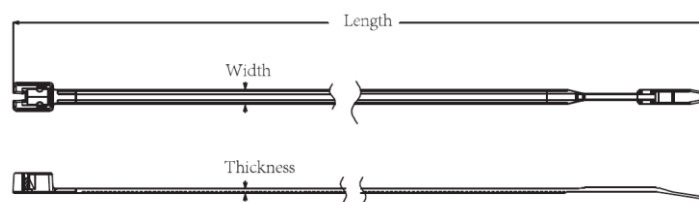

Please refer to our current catalogue for further details.

Our laboratory will be happy to advise you on resistance to aggressive media or specific oils.

Creator: PDP Released: PDP	Document: DB61850760DE Version: 00	Page 1 of 2
-------------------------------	---------------------------------------	-------------

61850760	DATA SHEET	
Valid from: 13.04.2026	CABLE TIE TWIST	

Dimension table:

Part No.	Bundle diameter E mm	Dimensions mm		Tensile strength N
		Length l	Width w	
Black				
61850760	49	200	4,8	222
61850765	70	280	4,8	222
61850770	102	370	4,8	222

* Testing of the maximum loop tensile strength

