

52122001	DATA SHEET	
Valid from: 06.03.2023	SKINDICHT® O-RING M FKM	

The SKINDICHT® O-ring FKM metric provide safe sealing against oil, water, alkalis, acids and extreme conditions at the connection thread of gland or similar parts.




Technical features:

Material	FKM
Sizes	M12 up to M63
Temperature range	-20 °C up to +200 °C
Hardness	70±5 Shore A
Colour	Green

Norm references:



Article designation	Inner Ø x cord thickness [mm]	Article No.
OV M12 x 2	9 x 2	52122000
OV M12 x 1,5	9 x 1,5	52122001
OV M16 x 2	13 x 2	52122010
OV M16 x 1,5	13 x 1,5	52122011
OV M20 x 2	17 x 2	52122020
OV M20 x 1,5	17 x 1,5	52122021
OV M25 x 2	22 x 2	52122030
OV M32 x 2	28 x 2	52122040
OV M40 x 2	36 x 2	52122050
OV M50 x 2	46 x 2	52122060
OV M63 x 2	57 x 2	52122070

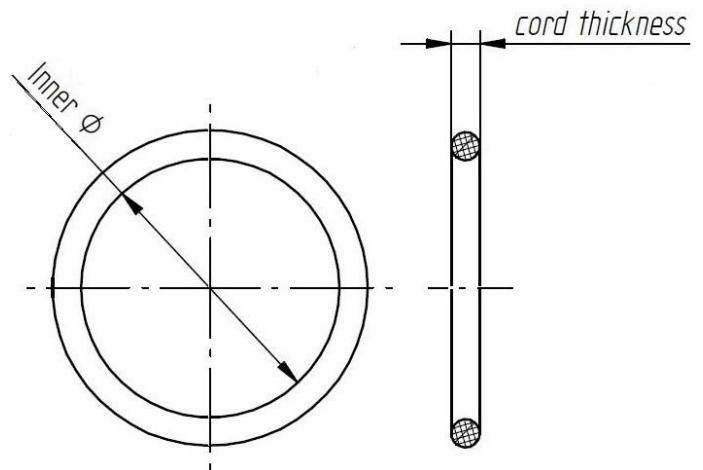

For more information please see our current catalogue. Please do not hesitate to contact our laboratory if there are any questions regarding resistance against aggressive agents and special oil.

Creator: M. Wegerer /PDP Released: DAMU1/PDP	Document: DB52122001EN Version: 04	Page 1 of 1
---	---------------------------------------	-------------