

CE6326	INSTALLATION GUIDE	
Valid from: 03.12.2019	EPIC CE6326 RJ45 Connector for MCS 8 RJ45	


Description

- RJ45 connector for use in module MCS 8 RJ45
- For data transmission rates up to 100Mhz
- The mixed assembly guarantees high flexibility



Pin assignment


EIA/TIA 586A

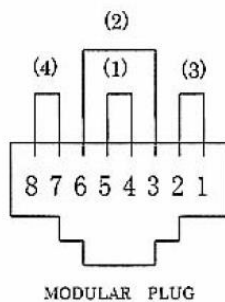

(1)---- : pair

1..... white /green
2..... green/ white
3..... white/ orange
4..... blue/white
5..... white/ blue
6..... orange/ white
7..... white/brown
8..... brown/ white

EIA/TIA 568B

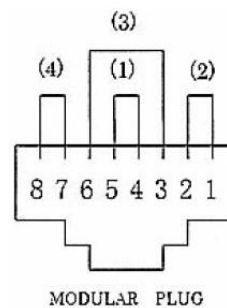

(1)---- : pair


1..... white/ orange
2..... orange/ white
3..... white /green
4..... blue/white
5..... white/ blue
6..... green/ white
7..... white/brown
8..... brown/ white

Instruction

- 1) Remove cable jacket




- 2) Arrange the wires

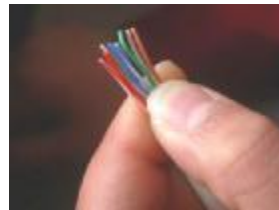

- 3) After arrangement, cut 2 to 5mm away



- 4) Assemble plug

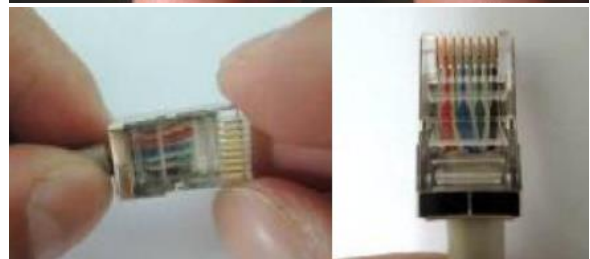

CE6326	INSTALLATION GUIDE	
Valid from: 03.12.2019	EPIC CE6326 RJ45 Connector for MCS 8 RJ45	

- 5) Crimping plug
 Remark: according to FCC standard
 H=5.98 to 6.08mm



- 6) Molding



Creator: FELI1/PDP Released: IVSE1/PDP	Document: BZCE6326EN Version: 01	Page 2 of 2
---	-------------------------------------	-------------