

7433501074	DATA SHEET	
Valid from: 19.02.2026	EPIC® MC04C2LSAB22CK20	

Description

- Sensor/actuator PVC-cable, unshielded
- M12 Connector, A-coding, 4 Pin



Product variations

Article no.	Article description	P1 - cable end	P2 - cable end	Length (mm)
7433501074	EPIC® MC04C2LSAB22CK20	coupling, straight	Open end	2000 + 100/-20
7433501075	EPIC® MC04C2LSAB22CK50	coupling, straight	Open end	2000 + 100/-20

Other lengths are available on request.

Connector, general characteristics

Coding	A-Coding
Number of poles / pins	4
Product standard	IEC 61076-2-101(2024)
Shielded	No
Protection class	IP 67
Pollution degree	3
Ambient temperature (connected)	-25 up to +80°C (Flexible) -40 up to +80°C (Fixed)
Plugging cycles	≥ 100
Tightening torque	Recommended:0.4 Nm Max:0.8 Nm

Connector, electrical properties

Rated voltage	250V AC OR DC
Rated surge voltage	2500 V
Rated current	4 A
Insulation resistance	≥ 100 MΩ
Contact resistance of connector	≤ 5 mΩ

Connector, materials

Contacts- Male connector	Brass, gold plated
Contacts- Female connector	Phosphor, gold plated
Insert	PA66+GF
Overmold	TPU/ Black
Threaded part	Brass, nickel plated
Sealing	FKM

Creator: Drake Long / PDCF Released: SOLI1 / PDCF	Document: DB7433501074EN Version: 00	Page 1 of 3
--	---	-------------

7433501074	DATA SHEET	
Valid from: 19.02.2026	EPIC® MC04C2LSAB22CK20	

Cable, general characteristics

AWM style	UL2464
Conductor cross-section	22 AWG(0.34mm ²)
Number of conductors	4 (1. Brown, 2. White, 3. Blue, 4. Black)
Core outer diameter	1.25 ±0.1mm
Jacket outer diameter	4.8±0.2mm
Cable weight	38 ± 3 kg/km
Temperature rating	VDE: -40 up to +80°C(Fixed) VDE: -5 up to +70°C(Fixed)
Flame resistance	Flame retardant acc .to IEC60332-1-2 UL: FT1 and VW1 CSA: FT1
Halogen-free	No
Oil resistance	No

Cable, electrical properties

Rated voltage	300 V
Conductor resistance	MAX 57 Ω/km at 20°C
Dielectric strength	2000V / min.



Cable, materials

Conductor	Bare copper
Conductor insulation	PVC
Jacket	PVC, Black


Creator: Drake Long / PDCF Released: SOLI1 / PDCF	Document: DB7433501074EN Version: 00	Page 2 of 3
--	---	-------------

7433501074	DATA SHEET	
Valid from: 19.02.2026	EPIC® MC04C2LSAB22CK20	


Drawings

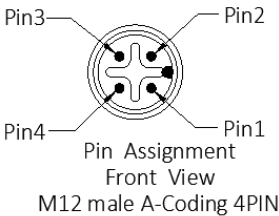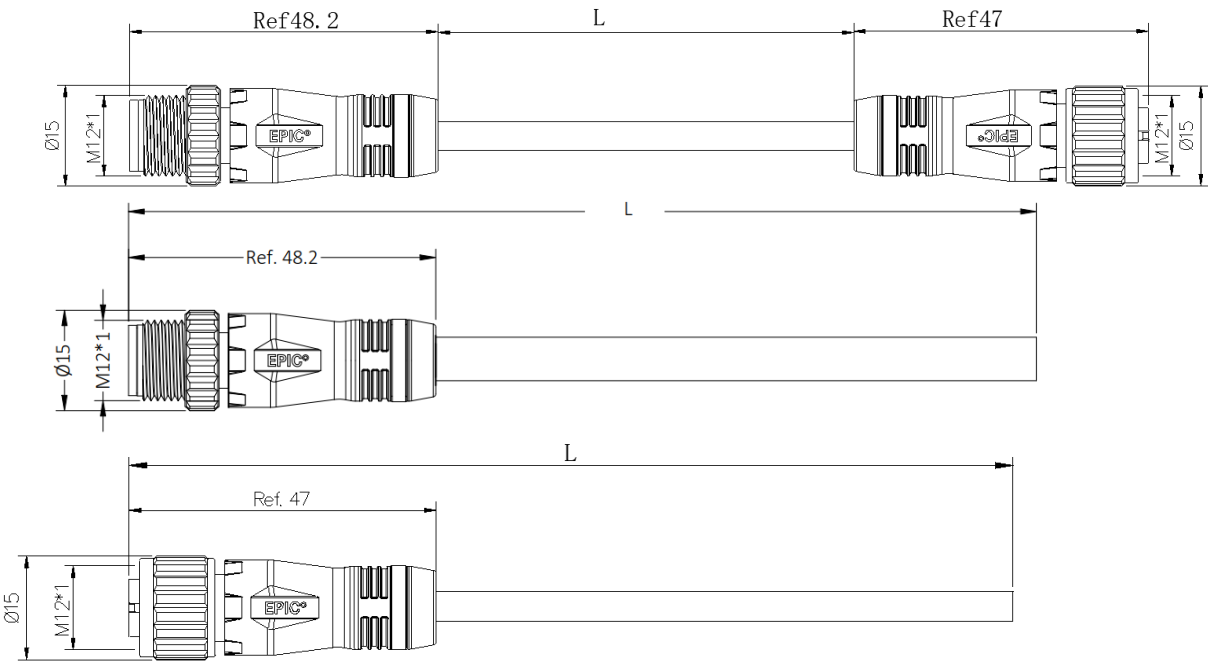

Wire List			
P1(male)			P2(female)
PIN 1	Brown	(AWG 22)	PIN 1
PIN 2	White	(AWG 22)	PIN 2
PIN 3	Blue	(AWG 22)	PIN 3
PIN 4	Black	(AWG 22)	PIN 4

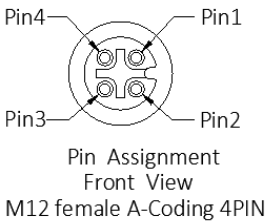

Cross section

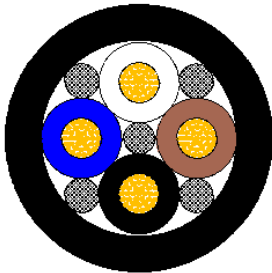

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Creator: Drake Long / PDCF Released: SOLI1 / PDCF	Document: DB7433501074EN Version: 00	Page 3 of 3
--	---	-------------