


7433500459	<b>DATA SHEET</b>	
Valid from: 19.02.2026	<b>EPIC® MB04C1LSAB24CK20</b>	

## Description

- Sensor/actuator PVC-cable, unshielded
- M8 Connector, A-coding, 4 Pin



## Product variations

Article no.	Article description	P1 - cable end	P2 - cable end	Length (mm)
7433500459	EPIC® MB04C1LSAB24CK20	Connector, straight	Open end	2000 +100/-20
7433500460	EPIC® MB04C1LSAB24CK50	Connector, straight	Open end	5000 +150/-30
7433500903	EPIC® MB04C3LSAB24CK50	Connector, straight	Coupling, straight	5000 +150/-30

Other lengths are available on request.


## Connector, general characteristics

Coding	A-Coding
Number of poles / pins	4
Product standard	IEC 61076-2-104(2014)
Shielded	No
Protection class	IP 67
Pollution degree	3
Ambient temperature (connected)	-25 up to +80°C (flexible) -40 up to +80°C (fixed)
Plugging cycles	≥ 100
Tightening torque	Recommended:0.2 Nm Max:0.4 Nm

## Connector, electrical properties

Rated voltage	60V DC/ 50V AC
Rated surge voltage	1500 V
Rated current	3 A
Insulation resistance	≥ 100 MΩ
Contact resistance of connector	≤ 5 mΩ

Creator: Drake Long / PDCF Released: SOLI1 / PDCF	Document: DB7433500459EN Version: 00	Page 1 of 3
--	---	-------------

7433500459	<b>DATA SHEET</b>	
Valid from: 19.02.2026	<b>EPIC® MB04C1LSAB24CK20</b>	

### Connector, materials

Contacts- Male connector	Brass, gold plated
Contacts- Female connector	Phosphor, gold plated
Insert	PA66+GF
Overmold	TPU/ Black
Threaded part	Brass, nickel plated
Sealing	FKM

### Cable, general characteristics

AWM style	UL2464
Conductor cross-section	24 AWG(0.25mm <sup>2</sup> )
Number of conductors	4 (1. Brown, 2. White, 3. Blue, 4. Black)
Core outer diameter	1.20 ±0.1mm
Jacket outer diameter	4.6±0.2mm
Cable weight	32 ± 3 kg/km
Temperature rating (Static)	-40 up to +80°C
Flame resistance	UL VW-1 IEC 60332-1-2 UL FT1
Halogen-free	No
Oil resistance	No

### Cable, electrical properties




Rated voltage	300 V
Conductor resistance	79 Ω/km at 20°C
Dielectric strength	2000V / min.

### Cable, materials

Conductor	Bare copper
Conductor insulation	PVC
Jacket	PVC, Black


Creator: Drake Long / PDCF Released: SOLI1 / PDCF	Document: DB7433500459EN Version: 00	Page 2 of 3
--	---	-------------

**Drawings**

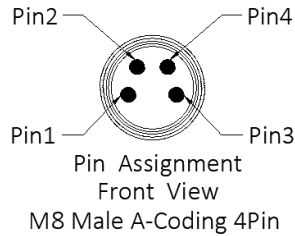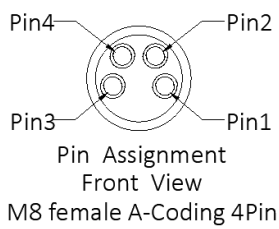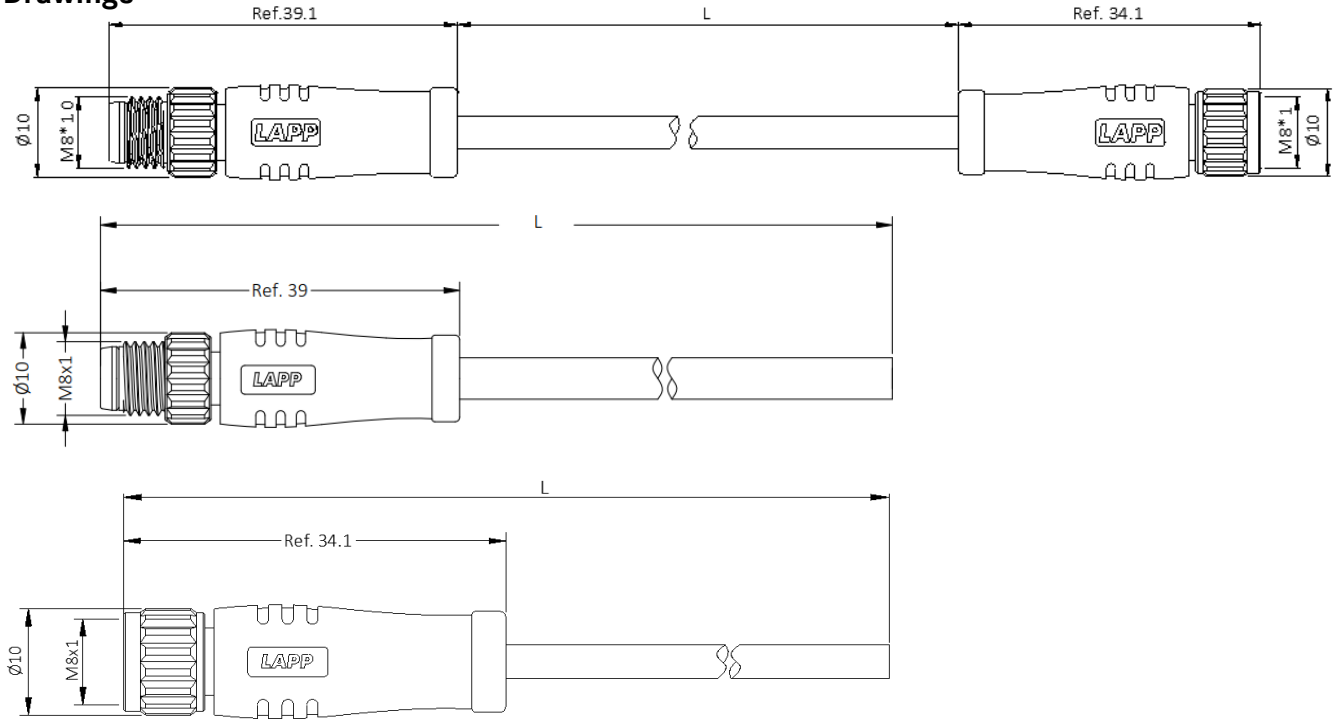

P1(male)	Wire List		P2(female)
PIN 1	Brown	(AWG 24)	PIN 1
PIN 2	White	(AWG 24)	PIN 2
PIN 3	Blue	(AWG 24)	PIN 3
PIN 4	Black	(AWG 24)	PIN 4

**Cross section**

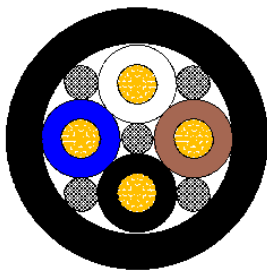

**Remark**

Photographs are not to scale and do not represent detailed images of the respective products.