

61804874	DATA SHEET
Valid from: 19.08.2025	FIPLOCK® ONE ST-M

Screw connection with strain relief suitable for FIPLOCK corrugated tubes.

Material:

Body Polyamide

Technical features:

Nominal width NW 10 to NW 29
Protection degree IP66, IP67, IP68 and IP69 according to EN 60529
In combination with FIPLOCK corrugated tubes
Temperature -45°C to +120°C

Additional features

Fire V0 acc. to UL94
Fire hazard rating HL2 R22 / HL3 R23 acc. to EN 45545-2
Oxygen index <32% acc. to EN ISO 4589-2
Halogen and cadmium free Yes
UV resistance Yes

Colour

Black
Grey

Approval



Reference standards:

IEC 61386-1
IEC 61386-23
EN 45545-2




Please refer to our current catalogue for further information.

Our laboratory will be happy to advise you on questions regarding resistance to aggressive media or specific oils.

Document: DB61804874EN Version: 00	Page 1 of 2
---------------------------------------	-------------

61804874	DATA SHEET
Valid from: 19.08.2025	FIPLOCK® ONE ST-M

Technical drawings:

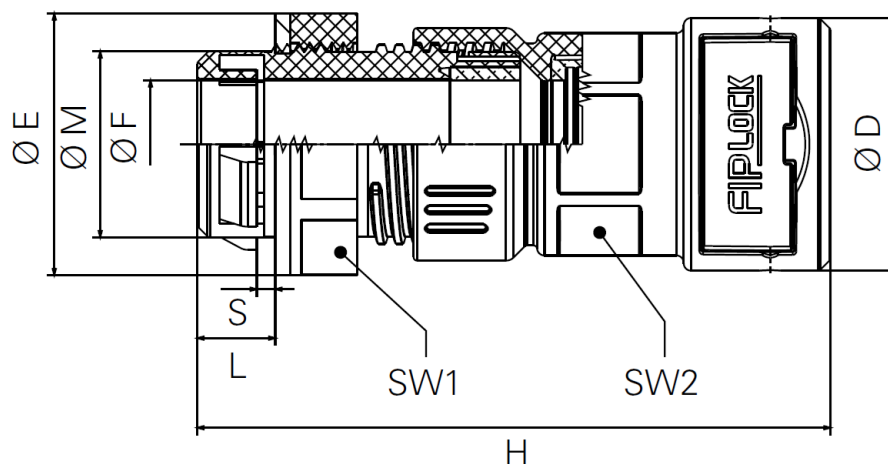

Dimension table:

Item no.	NW	L mm	S mm	H mm	Cable ØF mm	Hole ØM mm	ØE mm	ØD mm	SW 1	SW 2	Weight g
Black											
61804874	10	8	1,0-4,0	68,1	5 - 9	16,3	24,2	24,7	22	20	16
61804875	12	8	1,0-4,0	70,2	5 - 9	16,3	24,2	28,5	22	22	18
61804876	12	8	1,0-4,0	73,1	7 - 12	20,3	29,7	28,5	27	22	23
61804877	17	8	1,0-4,0	81,7	7 - 13	20,2	29,7	34,0	27	27	29
61804878	17	8	1,0-4,0	85,2	9 - 16,5	25,3	35,2	34,0	32	27	35
61804879	23	8	1,0-4,0	85,2	9 - 17	25,3	35,2	41,7	32	36	43
61804880	23	8	1,0-4,0	91,3	11 - 20	32,3	44,0	41,7	40	36	55
61804881	29	8	1,0-4,0	91,6	11 - 20	32,3	44,0	48,4	40	41	58
Grey											
61804882	10	8	1,0-4,0	68,1	5 - 9	16,3	24,2	24,7	22	20	16
61804883	12	8	1,0-4,0	70,2	5 - 9	16,3	24,2	28,5	22	22	18
61804884	12	8	1,0-4,0	73,1	7 - 12	20,3	29,7	28,5	27	22	23
61804885	17	8	1,0-4,0	81,7	7 - 13	20,2	29,7	34,0	27	27	29
61804886	17	8	1,0-4,0	85,2	9 - 16,5	25,3	35,2	34,0	32	27	35
61804887	23	8	1,0-4,0	85,2	9 - 17	25,3	35,2	41,7	32	36	43
61804888	23	8	1,0-4,0	91,3	11 - 20	32,3	44,0	41,7	40	36	55
61804889	29	8	1,0-4,0	91,6	11 - 20	32,3	44,0	48,4	40	41	58

Trade Product, not a Lapp product.