

29500010	DATA SHEET
Valid from: 10.04.2026	POF CRIMP TOOL 2.5/3.0/4.5/4.95MM

Description

- Crimp tool, hex profile
- Incl. 4-times crimping die (with 4 different wrench sizes)
- Suitable for optical fibre contacts on polymer optical fibre cables




General characteristics

Crimping die	Changeable
Weight (incl. crimping die)	0.551 kg
Dimensions (closed crimping position)	256 mm x 80 mm x 22 mm (B x L x H)
Material	plastic (handle) stainless steel (wrench)

die wrench area

die wrench size	POF-cable-Ø [mm]	suitable connectors
SW 2,5	2.2	SC
SW 3,0	2.2	F-SMA, F-ST
SW 4,5	2.2	HFBR simplex
SW 4,95	2.2 x 4.4	HFBR duplex

Technical drawing

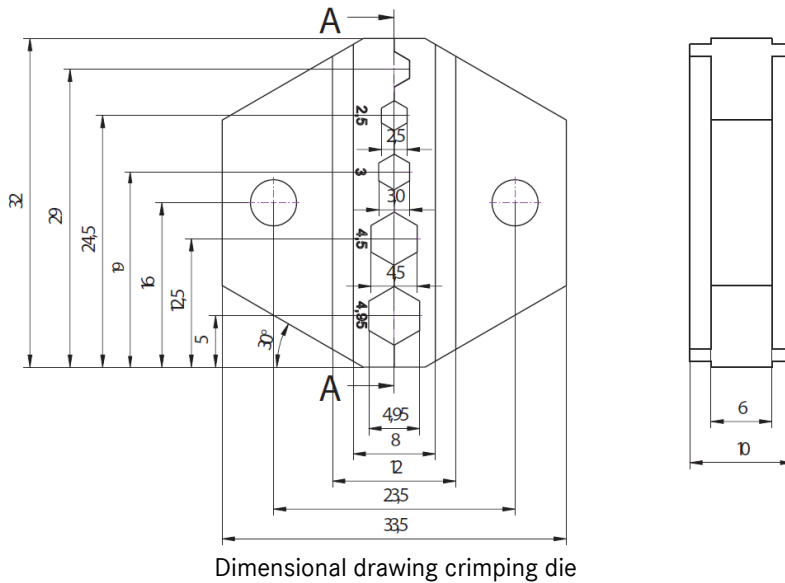

Application range

Assembly of optical connectors for optical networks, industry and power electronics, consumer electronics

Note

Photographs are not true to scale and do not represent detailed images of the respective products.
Use safety glasses to avoid eye injury. Use adequate hand protection.